

RMM 11/230 V OUTPUT RELAY

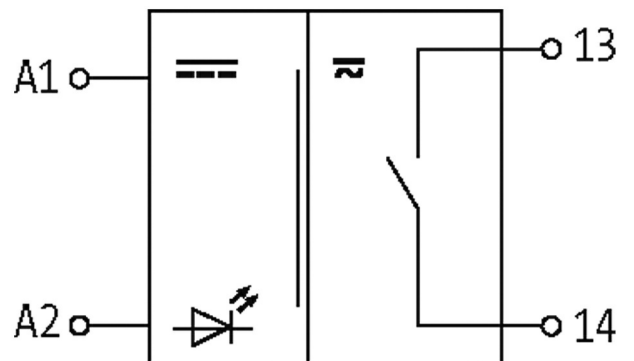
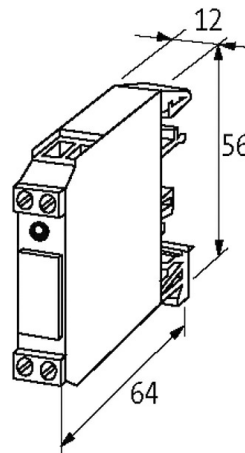
IN: 230 VAC/DC - OUT: 250 VAC/DC / 6 A

1 relay; 1 NO contact

6 A

230 V AC

Screw terminals

Illustration

Product may differ from Image

Input

Connection voltage - current	230 V AC/DC (195...250 V AC/DC) - 3.5 mA
------------------------------	--

LED display	LED (red)
-------------	-----------

Output

Switching voltage	max. 250 V AC/DC
-------------------	------------------

Switching current per output	max. 6 A
------------------------------	----------

Min. load current	100 mA
-------------------	--------

Power rating (voltage dependent)	max. 1250 VA/240 W
----------------------------------	--------------------

Switching frequency	max. 10 Hz
---------------------	------------

Contact material	Ag Ni 0.15 hv; Ag hv
------------------	----------------------

Energize/release/contact bounce time	10/15/1.5 ms
--------------------------------------	--------------

Utilization category

AC-12	6 A (24/110/230 V AC)
-------	-----------------------

AC-15	4 A (24/110/230 V AC)
-------	-----------------------

DC-13	2 A (24 V DC); 0.25 A (110 V DC); 0.1 A (230 V DC)
-------	--

General data

Mech./ elect. life	20 000 000 switching cycles/load dependent
--------------------	--

Test isolation voltage	4.0 kV
------------------------	--------

Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
-----------------	---

Temperature range	-20...+60 °C
-------------------	--------------

Dimensions H×W×D	56×12×65 mm
------------------	-------------

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85364900
-----------------------	----------

EAN	4048879027557
-----	---------------

eClass	27371001
--------	----------

Packaging unit	1
----------------	---