

RMMD 1S+1V24VDC INPUT RELAY

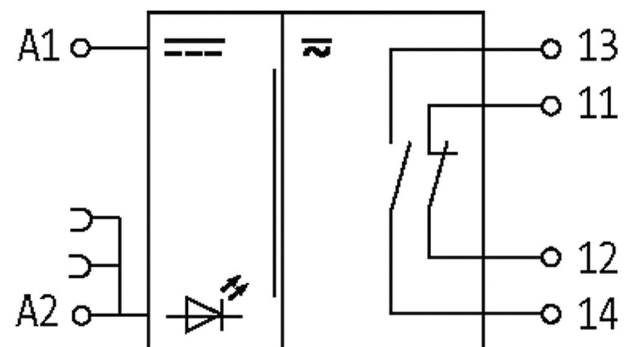
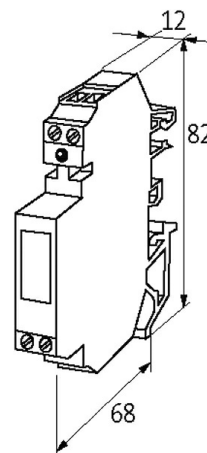
IN: 24 VDC - OUT: 250 VAC/DC / 3 A

1 relay; 1 NO contact/1 NC contact

3 A

24 V DC

Screw terminals

Illustration

Product may differ from Image

Input

Connection voltage - current	24 V DC (17.5...30 V DC) - 14 mA
------------------------------	----------------------------------

Plug link (supplied)	Art-No. 90960
----------------------	---------------

LED display	LED (red)
-------------	-----------

Output

Switching voltage	max. 250 V AC/DC
-------------------	------------------

Switching current per output	max. 3 A
------------------------------	----------

Min. load current	1 mA
-------------------	------

Power rating (voltage dependent)	max. 500 VA/180 W
----------------------------------	-------------------

Switching frequency	max. 10 Hz
---------------------	------------

Contact material	Ag Ni 0.15 hv
------------------	---------------

Energize/release/contact bounce time	6/3/2 ms
--------------------------------------	----------

Utilization category

AC-1	3 A (24 V AC); 2 A (230 V AC)
------	-------------------------------

AC-15	1 A (24 V AC); 0.1 A (230 V AC)
-------	---------------------------------

DC-13	0.8 A (24 V DC); 0.01 A (230 V DC)
-------	------------------------------------

General data

Mech./ elect. life	20 000 000 switching cycles/load dependent
--------------------	--

Test isolation voltage	2.5 kV
------------------------	--------

Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
-----------------	---

Temperature range	-20...+60 °C
-------------------	--------------

Dimensions H×W×D	82×12×68 mm
------------------	-------------

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85364900
-----------------------	----------

EAN	4048879024846
-----	---------------

eClass	27371601
--------	----------

Packaging unit	1
----------------	---