
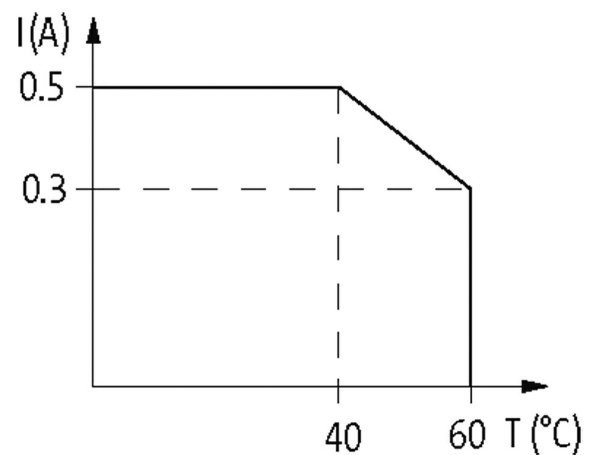
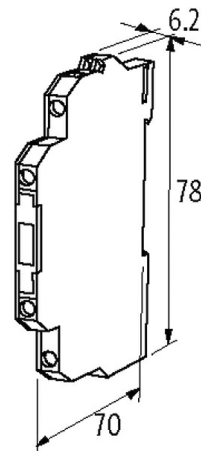


MIRO TR 24VDC SK OPTO-COUPLER MODULE

IN: 53 VDC - OUT: 48 VDC / 0,5 A

Transistor 0.5 A
24 V DC
Screw terminals

Illustration

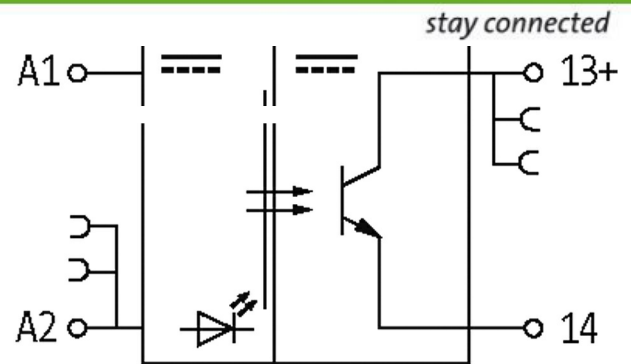

Product may differ from Image

Approvals



Input

Voltage range ON	10...53 V DC
Voltage range OFF	0...5 V DC
Control current	6 mA
LED display	LED (yellow)

Output

Switching voltage	5...48 V DC
Switching current per output	0.1 mA...0.5 A
Saturation voltage (across output)	max. 1.2 V DC
Leakage current (output is open)	max. 10 μ A
Switching time ON/OFF	35/400 μ s
Switching frequency	max. 1000/100 Hz (resist./ind.)

General data

Test isolation voltage	3.75 kV
Housing	Black plastic, flame retardant
Mounting method	DIN-rail mountable (EN 60715)
Temperature range	-20...+60 °C
Dimensions H×W×D	78×6.2×70 mm

Commercial data

country of origin	CZ
customs tariff number	85414090
EAN	4048879026949
eClass	27371604
Packaging unit	1