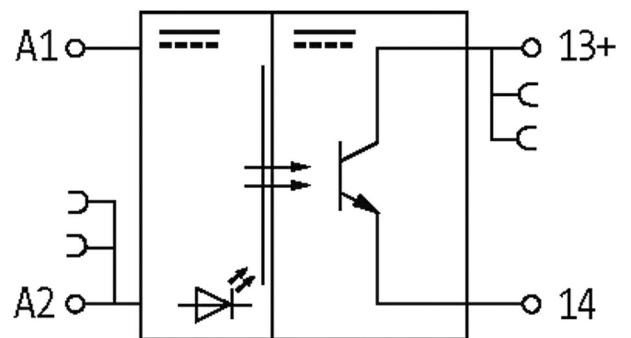
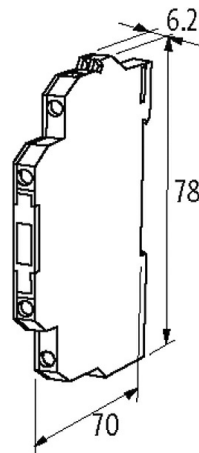


**MIRO TR 5VDC SK OPTO-COUPLER MODULE**

IN: 5,5 VDC - OUT: 48 VDC / 2 A

Transistor 2 A  
5 V DC  
Screw terminals

**Illustration**

Product may differ from Image

**Approvals**



Input	
Voltage range ON	4...5.5 V DC
Voltage range OFF	0...2 V DC
Control current	6 mA
LED display	LED (yellow)
Output	
Switching voltage	5...48 V DC
Switching current per output	1 mA...2 A
Saturation voltage (across output)	max. 0.3 V DC
Leakage current (output is open)	max. 10 $\mu$ A
Switching time ON/OFF	1/5 ms
Switching frequency	max. 10/1 Hz (resist./ind.)
General data	
Test isolation voltage	2.5 kV
Mounting method	DIN-rail mountable (EN 60715)
Housing	Black plastic, flame retardant
Temperature range	-20...+60 °C
Dimensions H×W×D	78×6.2×70 mm
Commercial data	
country of origin	CZ
customs tariff number	85414090
EAN	4048879026925
eClass	27371604
Packaging unit	1