


POTENTIAL TERMINAL BLOCK BROWN BLUE

Potential terminal block
brown/brown/blue/blue

Illustration

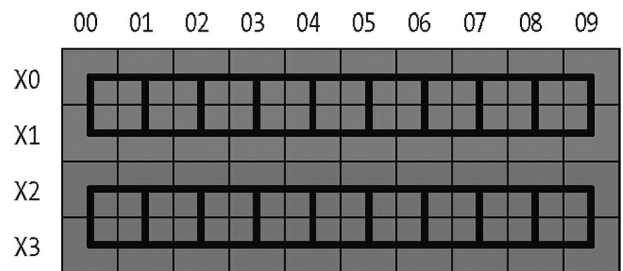

Product may differ from Image

Approvals



General data

Protection	IP20
Connection	Spring clamp terminals: 0.08...2.5 mm ² (AWG 28...14)
Dimensions H×W×D	70×56×32.5 mm
Temperature range	0...+55 °C (storage temperature -40...+85 °C)

Technical Data

Operating voltage	max. 30 V AC/DC
Total current	max. 10 A

Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879049375
eClass	27141106

Packaging unit	1
----------------	---

