

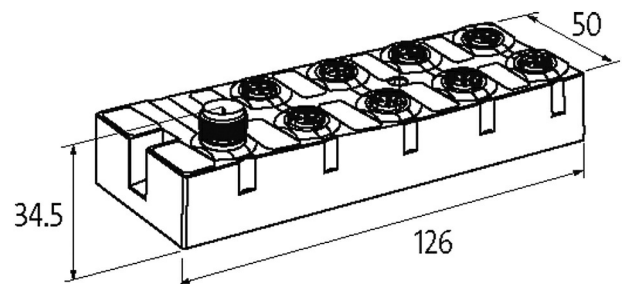
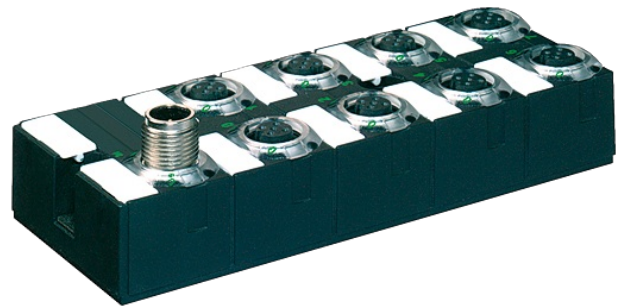
**MASI68 DI4/0,19A DO4/2A 8xM12**

Compact module

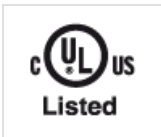
DI4 - 0.2 A DO4 - 2 A (C) - 8x M12

Connection cables are in the online shop under "Connection Technology".

Housing fully potted.

**Illustration**

Product may differ from Image

**Approvals****Input**

Sensor supply US max. 200 mA from AS-Interface (short-circuit and overload protected)

Type for 3-wire sensors or mechanical switches, PNP

**Output**

Switching current per output max. 2 A (short-circuit and overload protected)

Total current max. 4 A

**Connections**

Fieldbus A-coded

I/O ports M12, 5-pole

**General data**

Protection IP68

Mounting method screw fixing

Temperature range -20...+60 °C (storage temperature -20...+70 °C)

Dimensions HxWxD 126x50x34.5 mm

**Technical Data**

Bus voltage (AS-Interface)	26.5...31.6 V DC
ASI-Power 24	yes
Total current	max. 250 mA
Addressing	via master or M12 connection and programming device
Address range	1...31
Profile (IO/ID/ID2 code)	S-7.0.7

**Diagnostic**

Communication status	via LED
Diagnostic via LED	per module
Monitoring - no voltage	yes

**Commercial data**

country of origin	DE
customs tariff number	85176200
EAN	4048879048798
eClass	27242604
Packaging unit	1