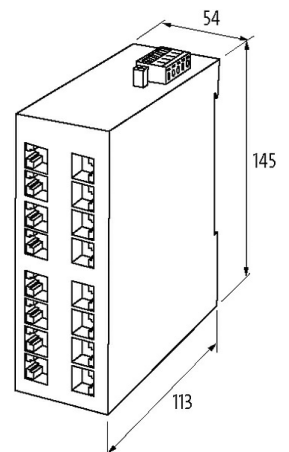


TREE 16 TX Metall 2GE 14 FE - Unmanaged Gigabit Switch - 16 Ports/

TREE 16 TX Metall 2GE 14 FE - Unmanaged Gigabit Switch - 16 ports

16 port unmanaged switch

Connection cables are in the online shop under "Connection Technology".

Illustration

Product may differ from Image

Approvals**Input**

Input current max. 0.8 A

Connections

Fieldbus 16× RJ45 (14× 100 Mbit/s, 2× 1000 Mbit/s)

Supply Screw plug-in terminal: 0.2...1.5 mm²**General data**

Protection IP30

Housing	Metal black
Mounting method	DIN-rail mountable TH35 (EN 60715)
Temperature range	0...+70 °C (storage temperature -20...+70 °C)
Dimensions H×W×D	145×54×113 mm

Technical Data

Operating voltage	IP502× 9...48 V DC, redundancy
Transfer rate	10/100/1000 Mbit/s full duplex
Input current	7.4 W
Operating modes	Autocrossing Autonegotiation

Switch Management

Switch Form	Unmanaged Switch
Webserver	no
VLAN (QoS) IEEE 802.p	yes
Port Mirroring	no
Protocols	no
Remote maintenance	no
Alarm contact	no

Diagnostic

Communication status	via LED
Monitoring - no voltage	yes

Commercial data

country of origin	TW
customs tariff number	85176200
EAN	4048879762076
eClass	19170106
Packaging unit	1