

## 10 Port unmanaged Gigabit Switch 4 PoE 2 SFP Ports IP20 metal

10 (4PoE, 2SFP) port unmanaged switch

Gigabit

Ethernet

Voltage booster (PoE)


Connection cables are in the online shop under "Connection Technology".

### Illustration



Product may differ from Image

### Approvals

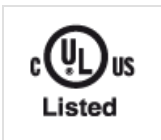

### Connections

Fieldbus	6× RJ45; 2× SFP
Supply	Screw terminals

### Technical Data

Operating voltage	12...57 V DC
Operating current (PoE)	max. 7 A (12...23 V DC); max. 6 A (24...57 V DC)
Power (PoE)	max. 60 W (12...23 V DC); max. 120 W (24...57 V DC)
Voltage booster (PoE)	max. 120 W
PoE	max. 30 W (per port)
Transfer rate	10/100/1000 Mbit/s full duplex
Operating modes	Autocrossing Autonegotiation

### Switch Management

Switch Form	unmanaged
Websserver	no
VLAN (QoS) IEEE 802.p	no
Port Mirroring	no
Protocols	no
Remote maintenance	no

Alarm contact	yes
Jumbo Frames	yes
IEEE 802.3 of	yes
IEEE 802.3 at	yes

**General data**

Protection	IP20
Housing	Metal black
Mounting method	DIN-rail mountable TH35 (EN 60715)
Temperature range	-40...+70 °C (storage temperature -40...+85 °C)
Dimensions H×W×D	145×57.8×113 mm

**Diagnostic**

Communication status	via LED
Monitoring - no voltage	yes

**Commercial data**

country of origin	TW
customs tariff number	85176200
EAN	4048879844215
Packaging unit	1