


## Xelity 4TX Unmanaged Switch 4 Port 100Mbit

4 port unmanaged switch

Connection cables are in the online shop under "Connection Technology".

### Illustration

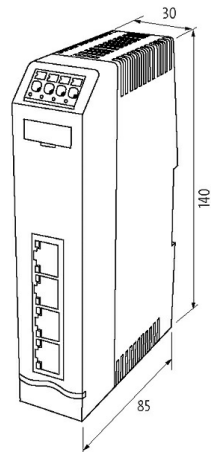

Product may differ from Image

### Approvals



### Connections

Fieldbus	4 x RJ45
Supply	Push-In spring clamp terminals, 0.2...2.5 mm <sup>2</sup> (0.25...1.5 mm <sup>2</sup> )

### General data

Protection	IP20
Housing	Black plastic
Mounting method	DIN-rail mountable TH35 (EN 60715)
Temperature range	-25...+60 °C (storage temperature -40...+85 °C)
Dimensions H×W×D	140×30×85.1 mm

**Technical Data**

Operating voltage	9.5...31.5 V
Transfer rate	10/100 Mbit/s full duplex
Operating modes	Autocrossing Autonegotiation

**Switch Management**

Switch Form	Unmanaged Switch
Webserver	no
VLAN (QoS) IEEE 802.p	yes
Port Mirroring	no
Protocols	no
Remote maintenance	no
Alarm contact	no

**Diagnostic**

Communication status	via LED
Monitoring - no voltage	yes

**Commercial data**

country of origin	DE
customs tariff number	85176200
EAN	4048879785952
eClass	19170106
Packaging unit	1