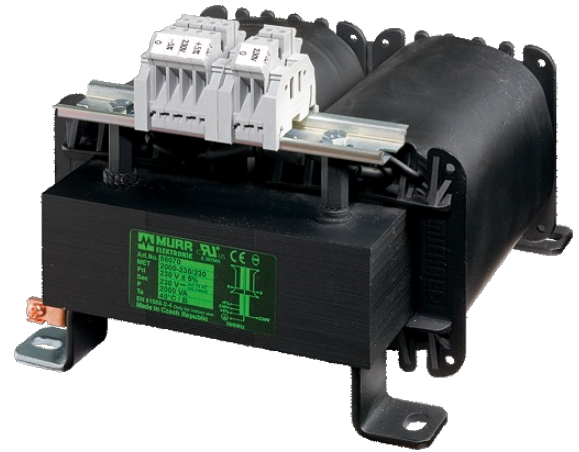


**MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER**

P: 3000VA IN: 230VAC+/- 5% OUT: 230VAC

Single-phase - Control and Isolation Transformers  
 3000 VA  
 Spring clamp terminals  
 Isolation class T 40/B

**Illustration**

Product may differ from image

**Approvals****Input**

Input voltage	230 V AC $\pm$ 5%
Frequency	50...60 Hz
Input current	13.6 A (230 V AC)
Short-circuit current	623.9 A (230 V AC)
Inrush current	209.9 A (230 V AC)

**Output**

Output voltage	230 V AC
Output rating	3000 VA

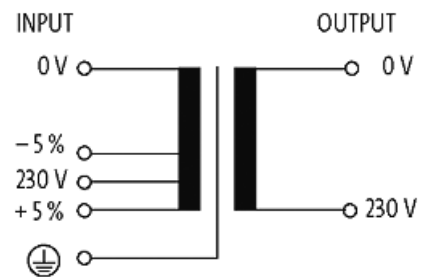
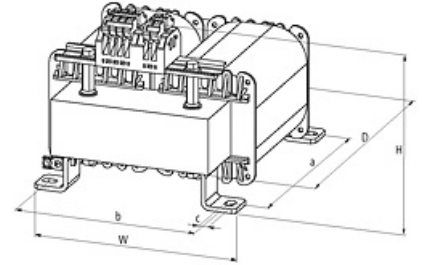
**General data**

Standards	EN 61558-1, EN 61558-2-4, EN 62041 category 0
Test isolation voltage	4 kV (prim./sec.)
Dimensions H×W×D	195×198×250 mm
Fixing centers a×b×c	200×174×9 mm
Drill hole $\varnothing$	9×14 mm
Mounting method	Long-hole mounting
Temperature range	-20...+40 °C (storage temperature -40...+80 °C)

**Commercial data**

country of origin	CZ
-------------------	----

customs tariff number	85043200
EAN	4048879066303
eClass	27031302
Packaging unit	1

**Sketch**

Product may differ from Image