

MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 5000VA IN: 400VAC+/- 5% OUT: 230VAC

Single-phase - Control and Isolation Transformers
 5000 VA
 Spring clamp terminals
 Isolation class T 40/B

Illustration

Product may differ from image

Approvals**Input**

Input voltage	400 V AC \pm 5%
Input current	12.86 A (400 V AC)
Short-circuit current	700.3 A (400 V AC)
Inrush current	254.2 A (400 V AC)
Frequency	50...60 Hz

Output

Output voltage	230 V AC
Output rating	5000 VA

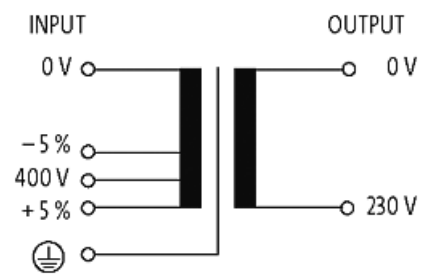
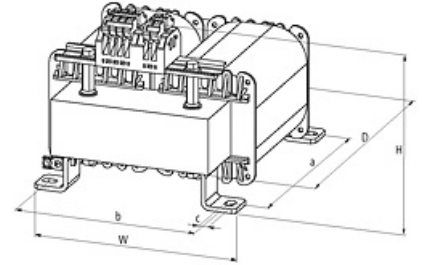
General data

Standards	EN 61558-1, EN 61558-2-4, EN 62041 category 0
Test isolation voltage	4 kV (prim./sec.)
Dimensions H×W×D	225×198×250 mm
Fixing centers a×b×c	200×174×9 mm
Drill hole \varnothing	9×14 mm
Mounting method	Long-hole mounting
Temperature range	-20...+40 °C (storage temperature -40...+80 °C)

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85043200
EAN	4048879066259
eClass	27031302
Packaging unit	1

Sketch

Product may differ from Image