

MSVD POWER SOCKET NEMA (GFCI)

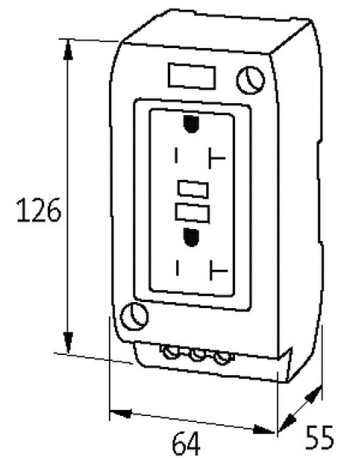
Mounting rail

USA (2× NEMA-GFCI 5-15)

(Ground Fault Circuit Interrupter)

Screw terminals

Each socket can be loaded with 20 A, however, the total load of both sockets must be below 30 A.

Illustration

Product may differ from Image

Approvals**General data**

Mounting method	DIN-rail mountable (EN 60715)
Connection	Screw terminals: max. 6 mm ²
Dimensions H×W×D	126×64×55 mm

Technical Data

Operating voltage	125 V AC
-------------------	----------

Operating current	max. 15 A
-------------------	-----------

Trip level	4...6 mA
------------	----------

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85366990
-----------------------	----------

EAN	4048879041393
-----	---------------

eClass	27189217
--------	----------

Packaging unit	1
----------------	---