

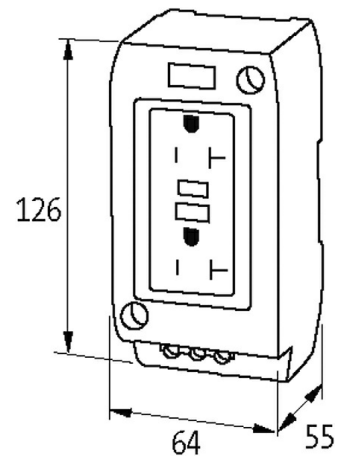
MSVD POWER SOCKET NEMA

Mounting rail

USA (2× NEMA 5-20)

Screw terminals

Each socket can be loaded with 20 A, however, the total load of both sockets must be below 30 A.

Illustration

Product may differ from Image

Approvals**General data**

Mounting method	DIN-rail mountable (EN 60715)
Connection	Screw terminals: max. 6 mm ²
Dimensions H×W×D	126×64×55 mm

Technical Data

Operating voltage	125 V AC
Operating current	max. 20 A

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879041362
eClass	27189217
Packaging unit	1