

Reset button with 1 push button

In a IP65 enclosure

R-Button / 42 1NO M12(4)

with M12 connection

4-pole

1 button (1 NO contact)

Delivery contents:

Flat lens, transparent clear, red, yellow, green, blue


Label plates, O, I, R

Illustration

stay connected



Male

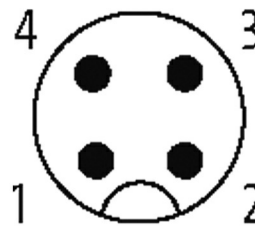


PIN 1: N/O 1

PIN 2: n.c.

PIN 3: n.c.

PIN 4: N/O 1

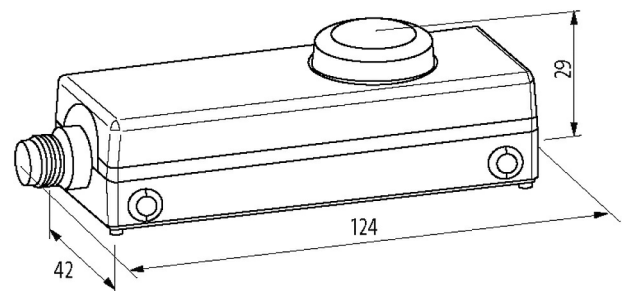

Product may differ from Image

Contact Layout

| | |
|-------|-------|
| PIN 1 | N/O 1 |
| PIN 2 | n.c. |
| PIN 3 | n.c. |
| PIN 4 | N/O 1 |

Components approvals

| | |
|-----------------------|----|
| Emergency-Stop button | UR |
| Housing | UR |

Utilization category

| | |
|-------|------------------|
| AC-15 | 1.5 A (240 V AC) |
|-------|------------------|

| | |
|-------|---------------|
| DC-13 | 2 A (24 V DC) |
|-------|---------------|

General data

| | |
|--------------------|--|
| Mech./ elect. life | 1 000 000 operations, load-temperature dependent |
|--------------------|--|

| | |
|--------------------|-------|
| Material (contact) | Ag Ni |
|--------------------|-------|

| | |
|------------|------|
| Protection | IP65 |
|------------|------|

| | |
|------------|--------------|
| Connection | M12 (4-pole) |
|------------|--------------|

| | |
|-----------------|-------------------|
| Mounting method | with clip on back |
|-----------------|-------------------|

| | |
|-------------------|---|
| Temperature range | -25...+70 °C (storage temperature -25...+85 °C) |
|-------------------|---|

| | |
|------------------|--------------|
| Dimensions H×W×D | 29×124×42 mm |
|------------------|--------------|

Technical Data

| | |
|--------------------|-----------------------------|
| Switching capacity | 15 A (AC 15); 2.2 A (DC 13) |
|--------------------|-----------------------------|

| | |
|---------------------|------------|
| Contact bounce time | max. 10 ms |
|---------------------|------------|

Commercial data

| | |
|-------------------|----|
| country of origin | DE |
|-------------------|----|

| | |
|-----------------------|----------|
| customs tariff number | 85365080 |
|-----------------------|----------|

| | |
|-----|---------------|
| EAN | 4048879594288 |
|-----|---------------|

| | |
|--------|----------|
| eClass | 27371244 |
|--------|----------|

| | |
|----------------|---|
| Packaging unit | 1 |
|----------------|---|