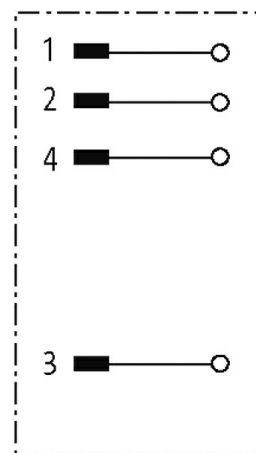
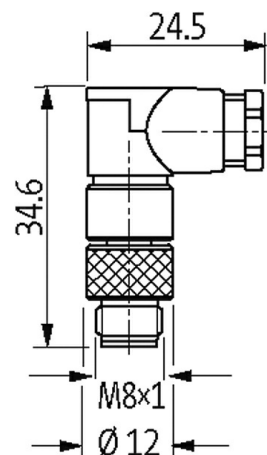


M8 MALE 90° FIELD-WIREABLE (SOLDER PINS)4-pol. 0.25mm²

Male 90°
M8, 4-pole
with solder pins
Connection cross section: max. 0.25 mm²

Illustration

Product may differ from Image

Form

Form

08461

General data

| | |
|-------------------|-----------------|
| Temperature range | -25...+85 °C |
| Dimensions H×W×D | 34.5×18.5×12 mm |

Technical Data

| | |
|-------------------------------|--|
| Operating voltage | max. 30 V AC/DC |
| Operating current per contact | max. 4 A |
| Connection cross section | max. 0.25 mm ² |
| Sealing range (cable Ø) | 3.5...5.0 mm |
| Protection | IP67 inserted and tightened (EN 60529) |

Commercial data

| | |
|-----------------------|---------------|
| country of origin | DE |
| customs tariff number | 85366990 |
| EAN | 4048879224635 |
| eClass | 27279221 |
| Packaging unit | 1 |

Sketch

Male



Product may differ from Image