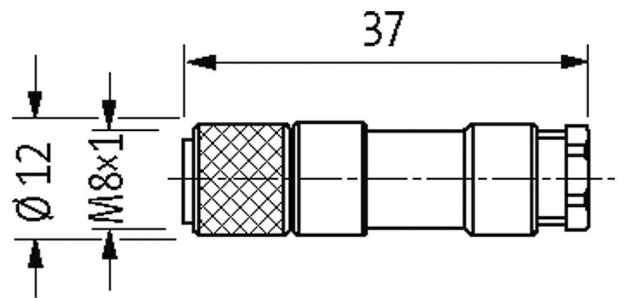


M8 FEMALE 0° FIELD-WIREABLE (SOLDER PINS)4-pol. 0.25mm²

Female straight

M8, 4-pole

with solder pins

Connection cross section: max. 0.25 mm²**Illustration**

Product may differ from Image

Form

Form 08501

General data

Temperature range	-25...+85 °C
Dimensions H×W×D	37×12×12 mm

Technical Data

Operating voltage	max. 30 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	max. 0.25 mm ²
Sealing range (cable Ø)	3.5...5.0 mm
Protection	IP67 inserted and tightened (EN 60529)


Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879224611
eClass	27279221
Packaging unit	1

Sketch

stay connected

Female

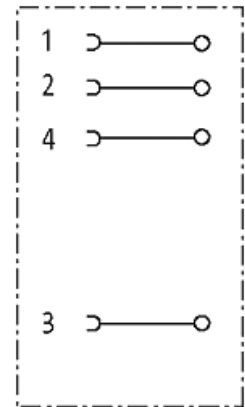

Product may differ from Image