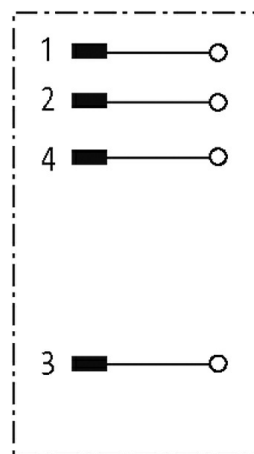
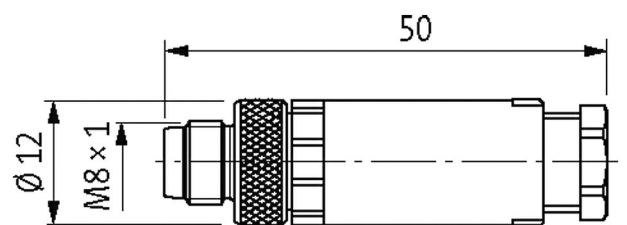


M8 MALE 0° FIELD-WIREABLE SCREW TERM.4-pol. 0,14...0.5mm²

Male straight

M8, 4-pole

Screw terminals

Connection cross section: 0.14...0.5 mm²**Illustration**

Product may differ from Image

Approvals**Form**

Form 08611

General data

Pollution Degree 3

Temperature range	-40...+85 °C
Material (housing)	PA
Material (contact)	Brass, gold plated
Dimensions H×W×D	50×12×12 mm

Technical Data

Operating voltage	max. 60 V
Operating voltage (only UL listed)	30 V
Rated surge voltage	1.5 kV
Operating current per contact	max. 4 A
Material group	III
Connection cross section	0.14...0.5 mm ²
Sealing range (cable Ø)	3.5...5.0 mm
Protection	IP67 inserted and tightened (EN 60529)
Over voltage category	III

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879224529
eClass	27279221
Packaging unit	1

Sketch

Male



Product may differ from Image