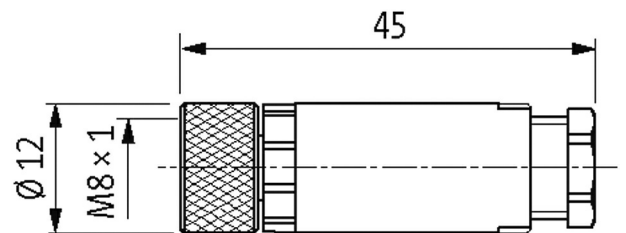


**M8 FEMALE 0° FIELD-WIREABLE SCREW TERM.**3-pol. 0,14...0.5mm<sup>2</sup>


Female straight

M8, 3-pole

Screw terminals

Connection cross section: 0.14...0.5 mm<sup>2</sup>**Illustration**

Product may differ from Image

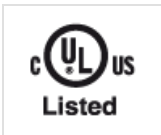**Approvals****Form**

Form 08621

**General data**

Pollution Degree	3
Temperature range	-40...+85 °C
Material (housing)	PA
Material (contact)	Brass, gold plated
Dimensions H×W×D	45×12×12 mm

**Technical Data**

Operating voltage	max. 60 V
Operating voltage (only UL listed)	30 V
Rated surge voltage	1.5 kV
Operating current per contact	max. 4 A
Material group	III
Connection cross section	0.14...0.5 mm <sup>2</sup>
Sealing range (cable Ø)	2.5...5.0 mm

Protection	IP67 inserted and tightened (EN 60529)
------------	--

Over voltage category	III
-----------------------	-----

**Commercial data**

country of origin	DE
-------------------	----

customs tariff number	85366990
-----------------------	----------



EAN	4048879224512
-----	---------------

eClass	27279221
--------	----------

Packaging unit	1
----------------	---

**Sketch**

Female

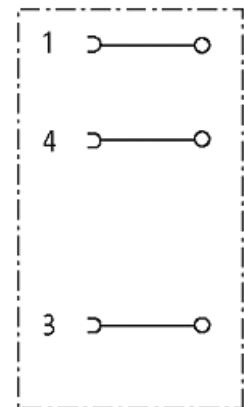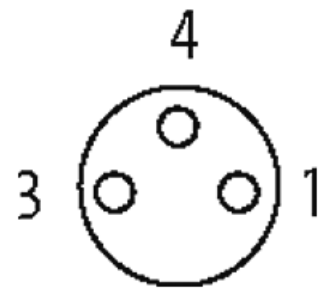

Product may differ from Image