


M8 FEMALE 0° SHIELDED WIREABLE SCREW TERM.4-pol. 0,14...0.5mm²

Female straight

M8, 4-pole

shielded

Screw terminals

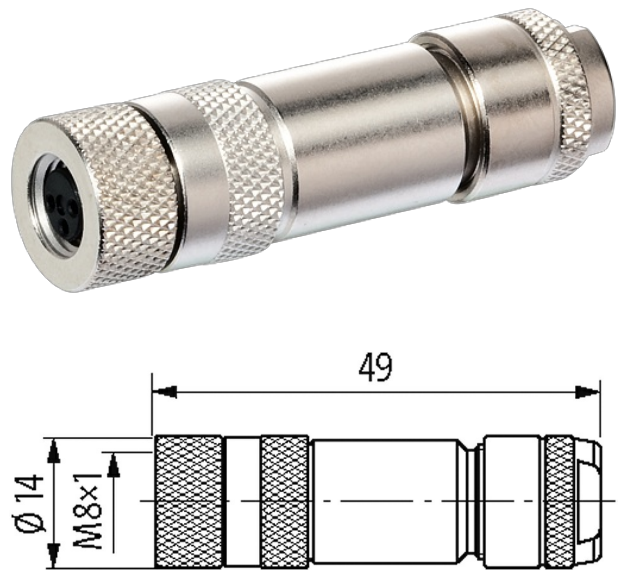Connection cross section: 0.14...0.5 mm²**Illustration**

Product may differ from Image

Form

Form 08671

General data

Pollution Degree	3
Temperature range	-40...+85 °C
Material (contact)	Gold plated bronze
Dimensions H×W×D	49×14×14 mm

Technical Data

Operating voltage	max. 60 V
Rated surge voltage	1.5 kV
Operating current per contact	max. 4 A
Material group	III
Connection cross section	0.14...0.5 mm ²
Sealing range (cable Ø)	4...5.5 mm
Protection	IP67 inserted and tightened (EN 60529)
Over voltage category	III

Commercial data



country of origin	DE
customs tariff number	85366990
EAN	4048879224468

eClass 27279221

Packaging unit 1

Sketch

Female

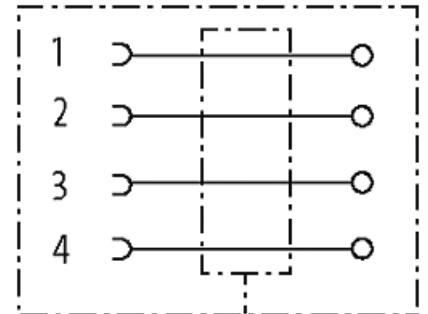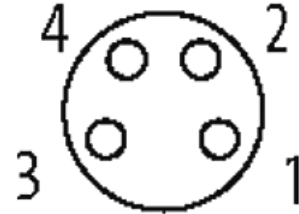

Product may differ from Image