

MOSA M12 MALE 0° FIELD-WIREABLE (IDC)5-pol., 0,34-0.5mm²

Male straight

M12, 5-pole


IDC terminals

Connection cross section: 0.34...0.5 mm²

The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

Male

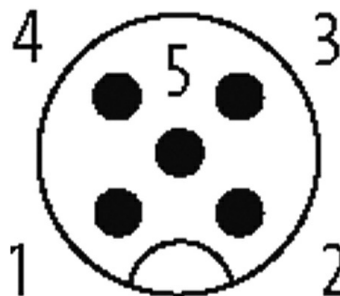

Product may differ from Image

Approvals**Form**

Form 12533

General data

Temperature range -25...+85 °C

Dimensions H×W×D 52.4×20.5×20.5 mm

Technical Data


Operating voltage max. 50 V AC/DC

Operating current per contact max. 4 A

Connection cross section	0.34...0.5 mm ² (conductor diameter min. 0.1 mm)
Sealing range (cable Ø)	4.7...6 mm
Wire isolation	PVC, PP
Outer wire Ø	1.2...2.0 mm
Protection	IP67 inserted and tightened (EN 60529)

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879306010
eClass	27279221
Packaging unit	1

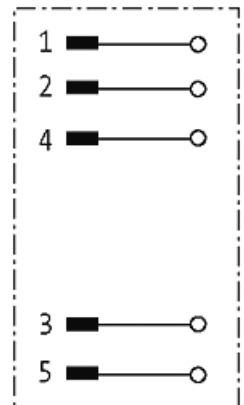Sketch

Product may differ from Image