

MOSA M12 FEMALE 0° FIELD-WIREABLE (IDC)5-pol., 0,34-0.5mm²

Female straight

M12, 5-pole


IDC terminals

Connection cross section: 0.34...0.5 mm²

The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

Female

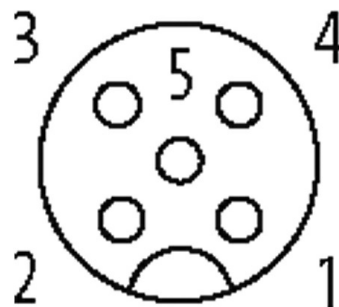

Product may differ from Image

Approvals**Form**

Form 12593

Technical Data

Operating voltage	max. 50 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	0.34...0.5 mm ² (conductor diameter min. 0.1 mm)
Sealing range (cable Ø)	4.7...6 mm
Wire isolation	PVC, PP

Outer wire Ø	1.2...2.0 mm
Protection	IP67 inserted and tightened (EN 60529)

General data

Temperature range	-25...+85 °C
Dimensions H×W×D	49×20.5×20.5 mm

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879306003
eClass	27279221
Packaging unit	1