

MOSA M12 FEMALE 0° FIELD-WIREABLE (IDC)A-cod., 4-pol., 0,14-0,34mm², shielded

Female straight


M12, 4-pole

IDC terminals

Connection cross section: 0.14...0.34 mm²

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

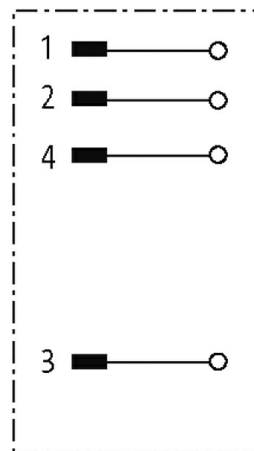Illustration

Product may differ from Image

Approvals**Form**

Form 12651

Technical Data

Operating voltage	max. 50 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	0.14...0.34 mm ² (conductor diameter min. 0.1 mm)

stay connected

Sealing range (cable Ø)	5.5...7.2 mm
Wire isolation	PVC, PP
Outer wire Ø	1.2...1.6 mm
Protection	IP67 inserted and tightened (EN 60529)

General data


Temperature range	-25...+85 °C
Dimensions H×W×D	49×19.5×19.5 mm

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879306034
eClass	27279221
Packaging unit	1

Sketch

Female

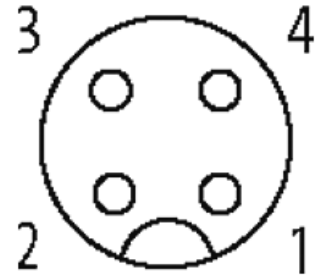

Product may differ from Image