

M12 MALE 0° FIELD-WIREABLE

Male straight


M12, 4-pole

Screw terminals

Sealing range (cable Ø): 8...10 mm

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

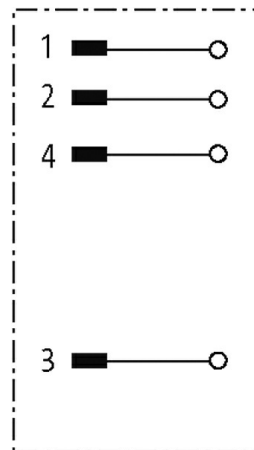Illustration

Product may differ from Image

Form

Form 12745

Technical Data

Operating voltage	max. 250 V AC/DC
Operating current per contact	max. 8 A
Connection cross section	max. 1.5 mm ²
Sealing range (cable Ø)	8...10 mm
Protection	IP67 inserted and tightened (EN 60529)

General data

Temperature range -25...+85 °C

Commercial data


country of origin	DE
customs tariff number	85366990
EAN	4048879378376

eClass 27279221

Packaging unit 1

Sketch

Male

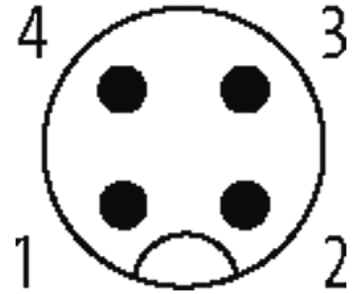

Product may differ from Image