

M12 MALE Y-DISTR. 0° WIREABLE SCREW TERM.5-pol. max.0,75mm²

Male straight

Y-connector M12, 5-pole

Screw terminals

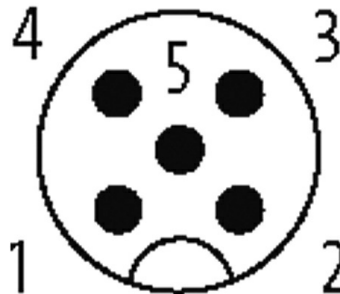
Sealing range (cable Ø): 2.1...3/4...5 mm

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

Male



Product may differ from Image

Form

Form 12801

General data

Temperature range -40...+85 °C

Dimensions H×W×D 63×20×20 mm

Technical Data

Operating voltage max. 125 V AC/DC

Operating current per contact max. 4 A

Connection cross section max. 0.75 mm²

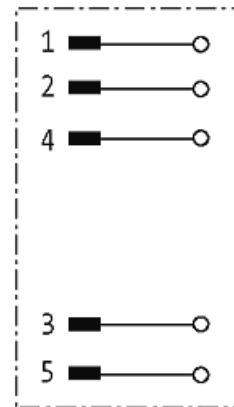
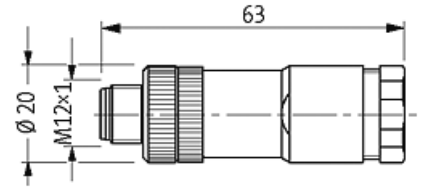
Sealing range (cable Ø) 2.1...3/4...5 mm (2 cable entries)

Protection IP67 inserted and tightened (EN 60529)

Commercial data

country of origin DE

customs tariff number	85366990
EAN	4048879201612
eClass	27279221
Packaging unit	1

Sketch

Product may differ from Image