

M12 MALE 90° SELF WIREABLE SCREW TERMINAL5-pol. 0,14 - 1,5mm², 2,5-8mm cable diameter

Male 90°

M12, 5-pole

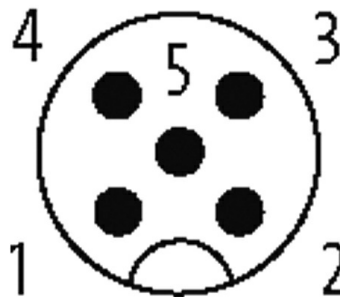
Screw terminals

Plastic housings with good resistance against chemicals and oils.

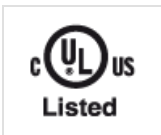
The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

Male



Product may differ from Image

Approvals**Form**

Form 12851

Technical Data

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 7.5 A (+40 °C; 1.5 mm ²)
Connection cross section	max. 1.5 mm ²
Sealing range (cable Ø)	2.5...8.0 mm

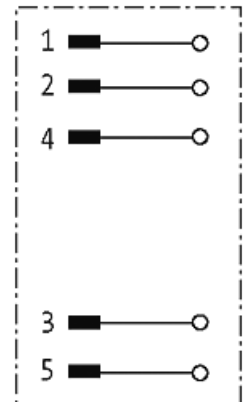
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm
Protection	IP67 inserted and tightened (EN 60529)

General data

Temperature range	-30...+85 °C
Dimensions H×W×D	46×38×20 mm

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879438247
eClass	27279221
Packaging unit	1

Sketch

Product may differ from Image