

M12 MALE 90° FIELD-WIREABLE SCREW TERM.4-pol. max.0,75mm² 6-8mm

Male 90°


M12, 4-pole

Screw terminals

Sealing range (cable Ø): 6...8 mm

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

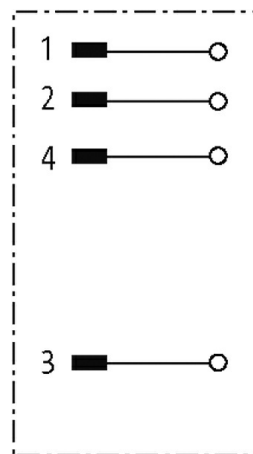Illustration

Product may differ from Image

Approvals**Form**

Form 12861

Technical Data

Operating voltage	max. 250 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	max. 0.75 mm ²
Sealing range (cable Ø)	6...8 mm

Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)

General data


Temperature range	-40...+85 °C
Dimensions H×W×D	41×35×20 mm

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879201582
eClass	27279221
Packaging unit	1

Sketch

Male

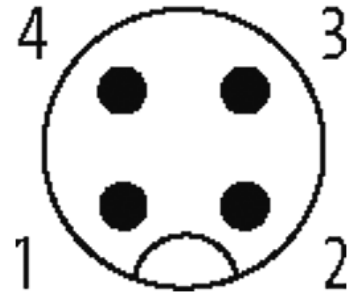

Product may differ from Image