

M12 MALE 0° SHIELDED WIREABLE SCREW TERM.5-pol. max.0,75mm² 4-6mm

Male straight

M12, 5-pole


shielded

Screw terminals

Sealing range (cable Ø): 4...6 mm

Illustration

Male

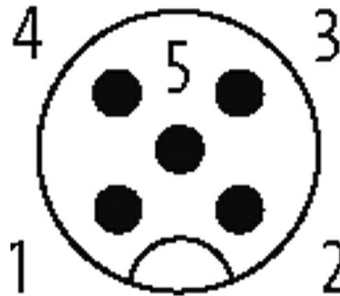

Product may differ from Image

Form

Form 13301

Technical Data

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	max. 0.75 mm ²
Sealing range (cable Ø)	4...6 mm
Protection	IP67 inserted and tightened (EN 60529)
Housing	Brass, nickel plated

General data


Temperature range -40...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879198844

eClass 27279221

Packaging unit 1

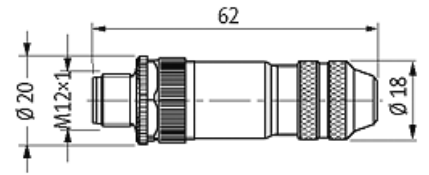Sketch

Product may differ from Image