

M12 MALE 0° SHIELDED WIREABLE SCREW TERM.5-pol. max.0,75mm² 6-8mm

Male straight

M12, 5-pole

A-coded


shielded

Screw terminals

Sealing range (cable Ø): 6...8 mm

Illustration

Male

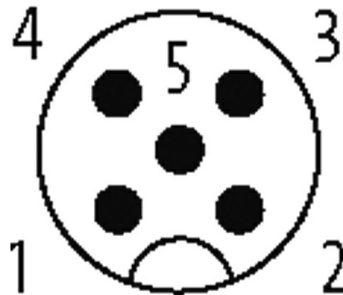

Product may differ from Image

Approvals**Form**

Form 13321

Technical Data

Operating voltage	max. 60 V
Rated surge voltage	0.8 kV
Operating current per contact	max. 4 A; max. 3 A (UL-Recognized)
Material group	III
Connection cross section	max. 0.75 mm ²
Sealing range (cable Ø)	6...8 mm


Over voltage category	II
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Compression gland	M12 (SW18)
Protection	IP67 inserted and tightened (EN 60529)

General data

Pollution Degree	3
Dimensions H×W×D	62×20×20 mm
Material (housing)	Zinc die casting, nickel-plated
Temperature range	-40...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879198837
eClass	27279221
Packaging unit	1

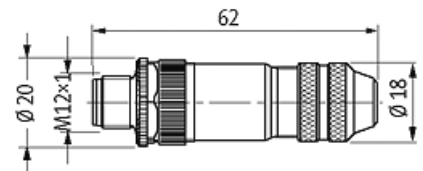Sketch

Product may differ from Image