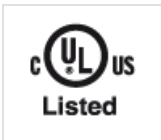


**M12 MALE 0° DIAGNOSTIC PLUG DESINA**

Blind plug diagnostic M12×1 mm  
Bridge PIN 1 + 2

**Illustration**

Product may differ from Image

**Approvals****Form**


Form 13481

**Technical Data**

Operating voltage	max. 30 V AC/DC
Operating voltage (only UL listed)	max. 30 V AC/DC
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879198745
eClass	23111190
Packaging unit	1

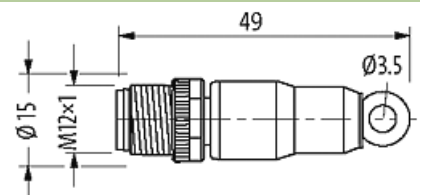**Sketch**

Product may differ from Image