

M12 FEMALE 0° B CODED SHIELDED WIREABLE SCREW TERM.2 POLE max. 0.75mm² 6-8mm PROFIBUS

Female straight

M12, 2-pole

B-coded



shielded

Screw terminals

Sealing range (cable Ø): 6...8 mm

Illustration

Female

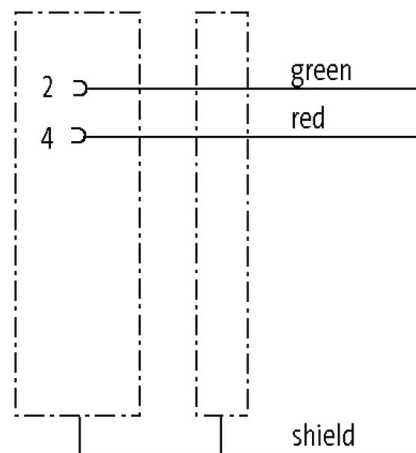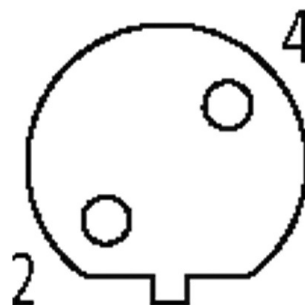

Product may differ from Image

Form

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 10/20

Form 14025

Technical Data


Operating voltage	max. 60 V
Operating current per contact	max. 4 A
Connection cross section	max. 0.75 mm ²
Sealing range (cable Ø)	6...8 mm
Housing	Brass, nickel plated
Protection	IP67 inserted and tightened (EN 60529)

General data

Temperature range -25...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879198615
eClass	27279221
Packaging unit	1

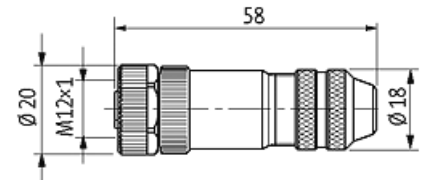Sketch

Product may differ from Image