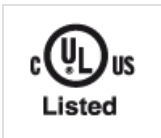


**M12 BUS TERMINATING PLUG FOR PROFIBUS**

PROFIBUS  
Terminating resistor  
Male  
M12, 4-pole  
B-coded

**Illustration**

Product may differ from Image

**Approvals****More Info****Form**

Form	14041
------	-------

**Technical Data**

Operating voltage	max. 30 V DC
Operating voltage (only UL listed)	max. 30 V DC
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated

**General data**




Temperature range	-25...+85 °C
-------------------	--------------

**Commercial data**

country of origin	DE
customs tariff number	85331000
EAN	4048879198592
eClass	19070403
Packaging unit	1

**Sketch**

# Male

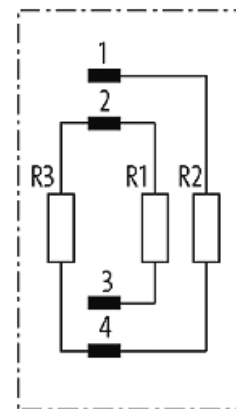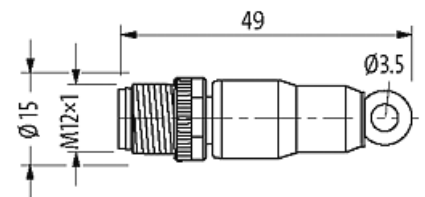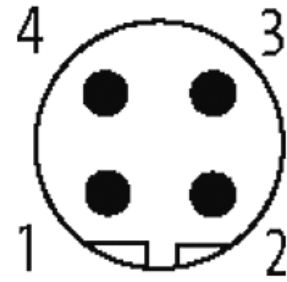

Product may differ from Image