

**BUS TERMINATING PLUG FOR PROFIBUS**

M12 female 0°, b-cod. with termination resistor

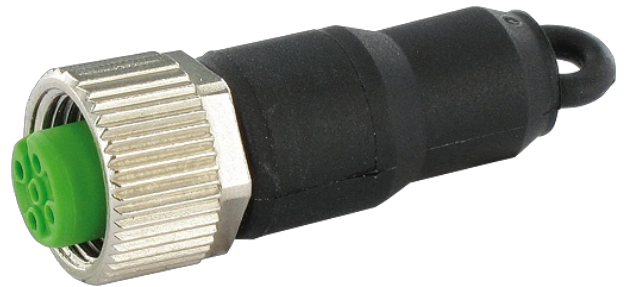
PROFIBUS

Terminating resistor

Female

M12, 4-pole

B-coded

**Illustration**

Product may differ from Image

**Approvals****More Info**

DeviceNet

**Form**

Form 14091

**Technical Data**

Operating voltage	max. 30 V DC
Operating voltage (only UL listed)	max. 30 V DC
Operating current per contact	max. 4 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Locking material	Zinc die casting, matte nickel plated

**General data**

Temperature range -25...+85 °C

**Commercial data**

country of origin	DE
customs tariff number	85331000
EAN	4048879419123
eClass	27061801
Packaging unit	1

