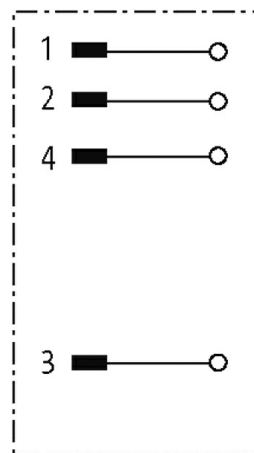


MOSA M12 MALE 0° FIELD-WIREABLE (IDC)B-cod., 2-pol., 0,25-0,34mm², shielded

PROFIBUS
Male straight
M12, 2-pole
B-coded
shielded
IDC terminals

Illustration

Product may differ from Image

Form

Form 14205

Technical Data

Operating voltage max. 32 V AC/DC

Operating current per contact max. 4 A

Connection cross section 0.25...0.34 mm² (AWG 22...24)

Sealing range (cable Ø) 4.5...8.8 mm

Outer wire Ø 2.0...2.6 mm

Protection IP67 inserted and tightened (EN 60529)

General data

Temperature range -25...+85 °C

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879331739
eClass	27279221
Packaging unit	1

Sketch

Male



Product may differ from Image