

**M12-Bus terminating plug for CUBE67**

Cube67

Terminating resistor

Male

M12, 6-pole



A-coded

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

**Illustration**

Male

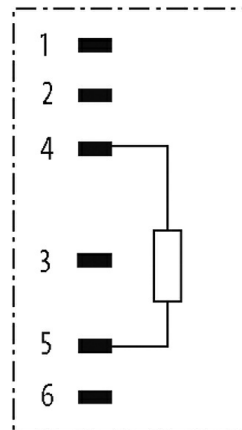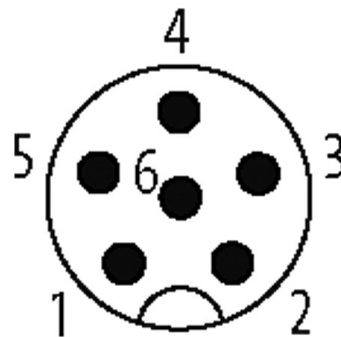

Product may differ from Image

**Approvals**

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 10/20

**Form**

Form 15041

**General data**

Temperature range -25...+85 °C

**Technical Data**

Operating voltage max. 30 V DC

Operating voltage (only UL listed) max. 30 V DC

Operating current per contact max. 4 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

**Commercial data**


country of origin DE

customs tariff number 85332100

EAN 4048879196963

eClass 19070403

Packaging unit 1

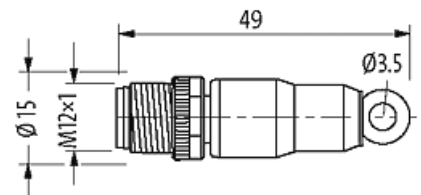**Sketch**

Product may differ from Image