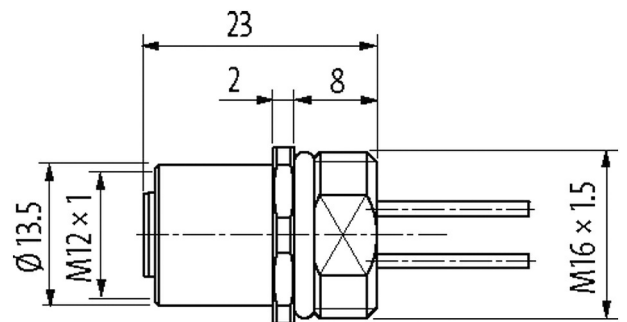



**M12 FEMALE FLANGE PLUG A CODED FRONT MOUNT**

PVC-wires 8x0,25 0.2m

Flange female  
M12, 8-pole  
Front mounting  
with multi-strand wire

**Illustration**

Female

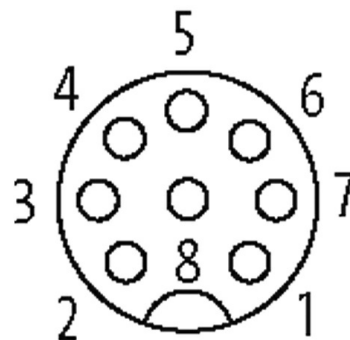

Product may differ from Image

**Approvals**

**Form**

Form 17181

**Cables**

Cable number	903
No./diameter of wires	8 × 0.25 mm <sup>2</sup>
Wire isolation	PVC (bl, wh, gn, ye, gr, pk, rd, br)
Outer Ø	1.15 mm ±5%
Bend radius (fixed)	12 × outer Ø
Temperature range (fixed)	-40...+105 °C
Temperature range (mobile)	-5...+105 °C

**Technical Data**


Operating voltage	max. 30 V AC/DC
Rated surge voltage	0.8 kV
Operating current per contact	max. 2 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Protection NEMA	3, 4, 6P (UL 50E)

**General data**

Temperature range -25...+85 °C

**Commercial data**

country of origin	DE
customs tariff number	85444290
EAN	4048879295031
eClass	27279220
Packaging unit	1

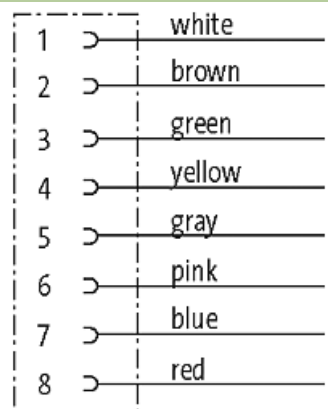**Sketch**

Product may differ from image