

**M12 MALE 0° FIELD-WIREABLE SCREW TERM.**8-pol. max.0.5mm<sup>2</sup> 6-8mm

Male straight

M12, 8-pole

Screw terminals

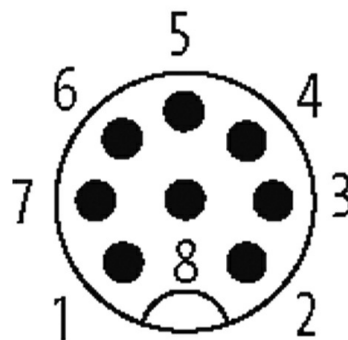
Sealing range (cable Ø): 6...8 mm

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

**Illustration**

Male



Product may differ from Image

**Approvals****Form**

Form 17301

**General data**

Temperature range -40...+85 °C

**Technical Data**

Operating voltage max. 30 V AC/DC

Operating current per contact max. 2 A

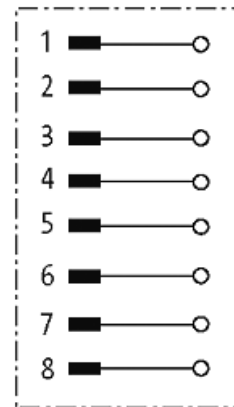
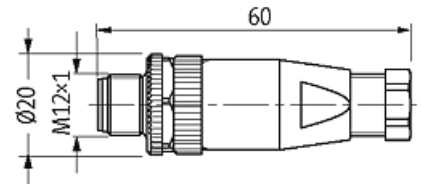
Connection cross section max. 0.5 mm<sup>2</sup>

Sealing range (cable Ø) 6...8 mm

Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879195355
eClass	27279221
Packaging unit	1

**Sketch**

Product may differ from Image