

**M12 MALE 0° SHIELDED WIREABLE SCREW TERM.**8-pol. max.0.5mm<sup>2</sup> 6-8mm

Male straight

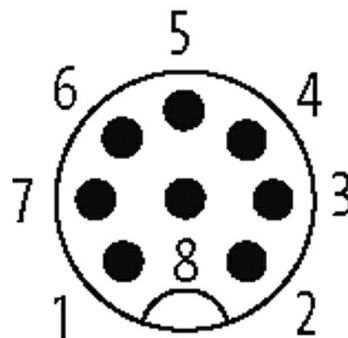
M12, 8-pole

shielded

Sealing range (cable Ø): 6...8 mm

**Illustration**

Male



Product may differ from Image

**Approvals****Form**

Form 17341

**Technical Data**

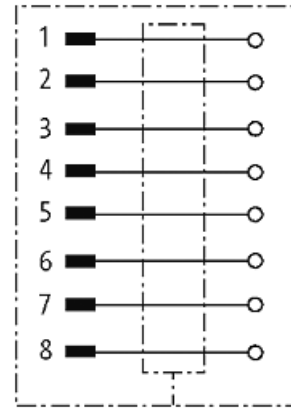
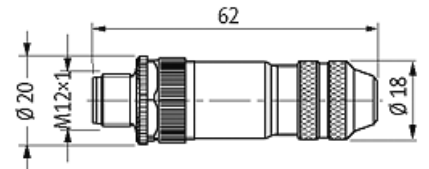
Operating voltage	max. 30 V AC/DC
Operating current per contact	max. 2 A
Connection cross section	max. 0.5 mm <sup>2</sup>
Sealing range (cable Ø)	6...8 mm
Protection	IP67 inserted and tightened (EN 60529)
Housing	Brass, nickel plated

**General data**

Temperature range -40...+85 °C

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879195317
eClass	27279221
Packaging unit	1

**Sketch**

Product may differ from Image