

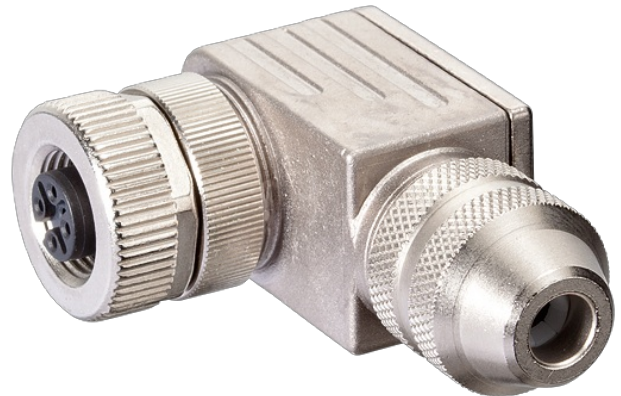
M12 FEMALE 90° SHIELDED WIREABLE SCREW TERM.8-pol. max.0.5mm² 6-8mm

Female 90°

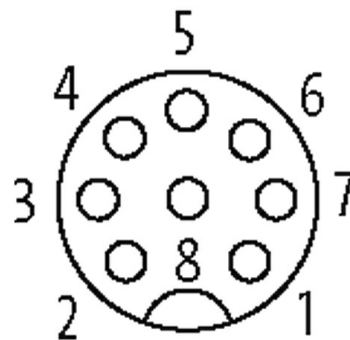
M12, 8-pole

shielded

Sealing range (cable Ø): 6...8 mm

Illustration

Female



Product may differ from Image

Approvals**Form**

Form 17371

Technical Data

Operating voltage max. 30 V AC/DC

Operating current per contact max. 2 A

Connection cross section max. 0.5 mm²

Sealing range (cable Ø) 6...8 mm

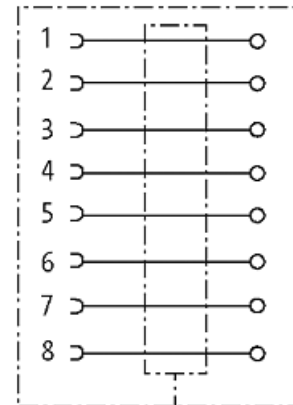
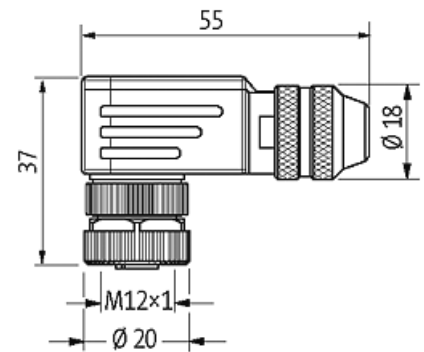
| | |
|------------|--|
| Protection | IP67 inserted and tightened (EN 60529) |
| Housing | Brass, nickel plated |

General data

| | |
|-------------------|--------------|
| Temperature range | -40...+85 °C |
|-------------------|--------------|

Commercial data

| | |
|-----------------------|---------------|
| country of origin | DE |
| customs tariff number | 85366990 |
| EAN | 4048879195287 |
| eClass | 27279221 |
| Packaging unit | 1 |

Sketch

Product may differ from Image