

MSUD VALVE PLUG FORM A 18MM

PVC 4X0.75 GRAY, UL/CSA 5m

MSUD

Form A (18 mm)

0...230 V AC/DC

without components


Further cable lengths on request.

Plastic housings with good resistance against chemicals and oils.



The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

stay connected

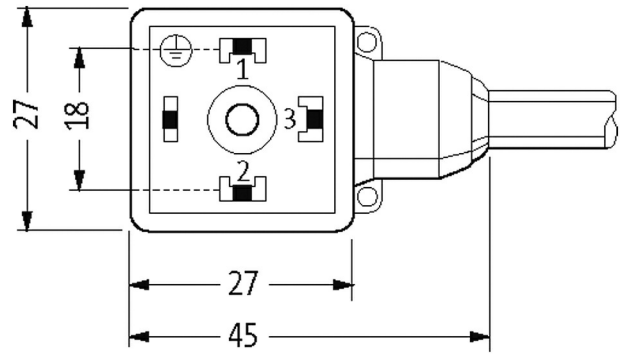

Height: 30 mm

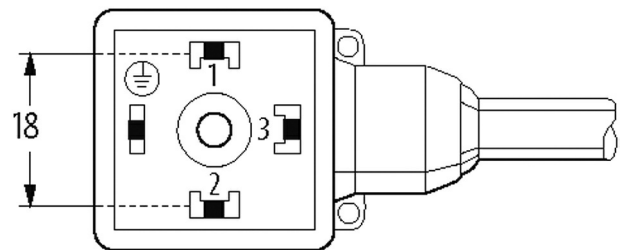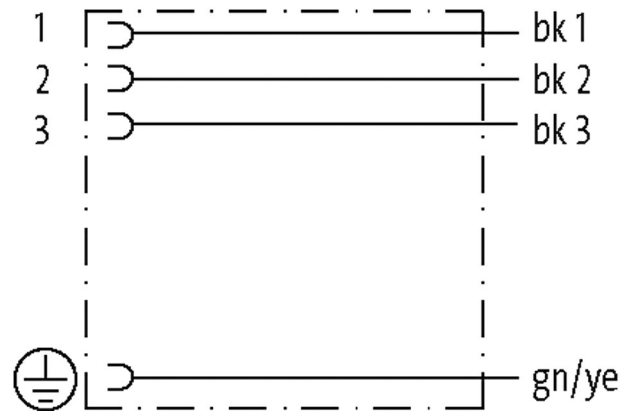

Product may differ from Image

Approvals



Form

Form 18111

Cables

| | |
|----------------------------|--|
| Cable number | 500 |
| No./diameter of wires | 4 × 0.75 mm ² |
| Wire isolation | PVC (bk num, gnye) |
| Jacket Color | gray |
| Material (jacket) | PVC (UL/CSA) |
| Outer Ø | 6.5 mm ±5% |
| Bend radius (moving) | 10 × outer Ø |
| Temperature range (fixed) | -40...+70 °C |
| Temperature range (mobile) | -5...+70 °C |
| Cable identification | 500 |
| Cable weight [g/m] | 77,00 |
| Material (wire) | Cu wire, bare |
| Resistor (core) | max. 26 Ω/km (20 °C) |
| Single wire Ø (core) | 0.2 mm |
| Construction (core) | 24 × 0.2 mm (multi-strand wire class 5) |
| Diameter (core) | 4 × 0.75 mm ² |
| AWG | similar to AWG 18 |
| Material (wire isolation) | PVC |
| Color/numbering of wires | bk numbered, gnye longitudinally striped |
| Stranding combination | 4 wires twisted |
| Shield | no |
| Material (jacket) | PVC |
| Outer-Ø (jacket) | 6.5 mm ±5% |
| Color (jacket) | gray |
| chemical resistance | good resistance to oil, gasoline and chemicals |
| Nominal voltage | 240 V AC |
| Test voltage | 2000 V AC |
| Temperature range (fixed) | -40...+70 °C |
| Temperature range (mobile) | -5...+70 °C |
| Bend radius (moving) | 10 × outer Ø |

Technical Data

| | |
|-------------------------------|---|
| Operating voltage | max. 230 V AC/DC |
| Operating current per contact | max. 10 A |
| Locking of ports | M3 (recommended torque 0.4 Nm) |
| Housing | Black plastic (gray on request) |
| Protection | IP66K, IP67 inserted and tightened (EN 60529) |

General data

Temperature range -25...+85 °C, depending on cable quality

Commercial data

| | |
|-----------------------|---------------|
| country of origin | CZ |
| customs tariff number | 85444290 |
| EAN | 4048879442091 |
| eClass | 27279218 |
| Packaging unit | 1 |