

M12 male 0° field-wireable C-Cod.

Male straight

M12, 3-pole

Sealing range (cable Ø): 4...6 mm

Screw terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals

* only for products with UL/CSA approved cable

Form

Form 20041

General data

Pollution Degree	3
Dimensions H×W×D	62×20×20 mm
Temperature range	-25...+85 °C

Technical Data


Operating voltage	max. 250 V AC/DC
Rated surge voltage	2.5 kV
Operating current per contact	max. 4 A
Material group	IEC 60664-1, category II
Connection cross section	max. 0.75 mm ²
Coding	M12, C-coded
Sealing range (cable Ø)	4...6 mm
Protection	IP67 inserted and tightened (EN 60529)
Material	PA

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879641975
eClass	27279221

Packaging unit 1

Sketch

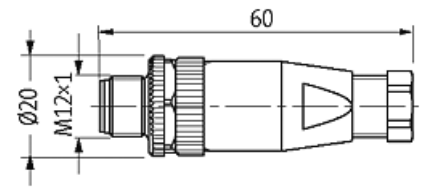

Product may differ from Image