

SVS VALVE PLUG FORM A 18MM FIELD-WIREABLE

24V LED+Z-Diode M16x1.5

Form A (18 mm)

24 V AC $\pm 20\%$ / DC $\pm 25\%$



LED and Z-diode

metric


Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

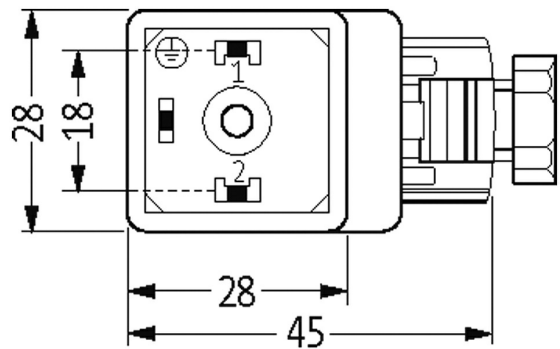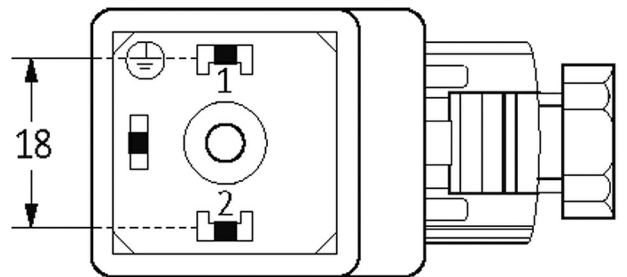

Height: 41 mm

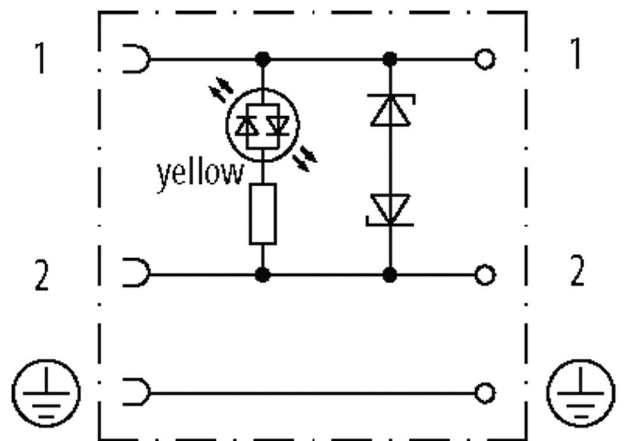

Product may differ from Image

Form

Form 29001

General data

Temperature range -20...+60 °C

Technical Data

Operating voltage 24 V AC/DC

Operating current per contact max. 4 A

Configuration 2 contacts + PE

Locking of ports M3 (recommended torque 0.4 Nm)

Protection IP65 inserted and tightened (EN 60529)

Tightening torque (clamp screw) 0.1 Nm

Sealing range (cable Ø) 5...10 mm

Commercial data

country of origin CN

customs tariff number 85366990

EAN 4048879187688

eClass 27279221

Packaging unit 1