

**SVS VALVE PLUG FORM A 18MM FIELD-WIREABLE**

230V LED+VDR PG9

Form A (18 mm)

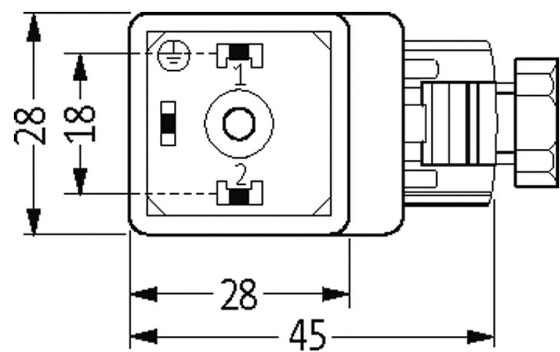
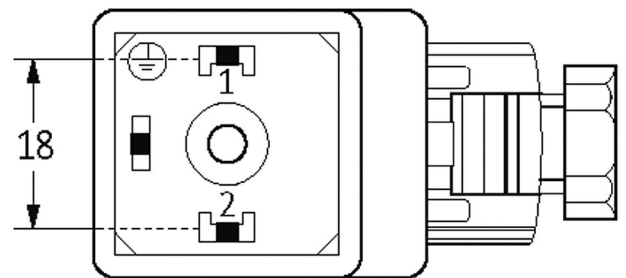
230 V AC/DC

LED and VDR

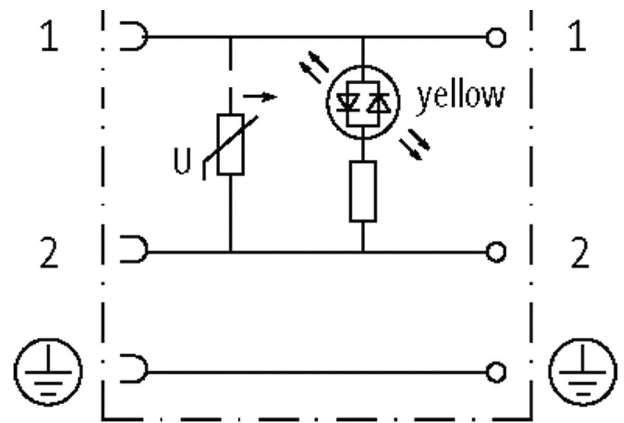
PG9

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Height: 41 mm



Product may differ from Image

### Form

Form 29181

### General data

Temperature range -20...+60 °C

### Technical Data

Operating voltage max. 230 V AC/DC

Operating current per contact max. 1 A

Configuration 2 contacts + PE

Locking of ports M3 (recommended torque 0.4 Nm)

Protection IP65 inserted and tightened (EN 60529)

### Commercial data

country of origin CZ

customs tariff number 85366990

EAN 4048879187541

eClass 27279221

Packaging unit 1