

**SVS ECO VALVE PLUG FORM A 18MM 230V**

2+PE field-wireable M16x1.5

Form A (18 mm)

250 V AC/DC

without components

metric



field-wireable

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

**Illustration**

*stay connected*

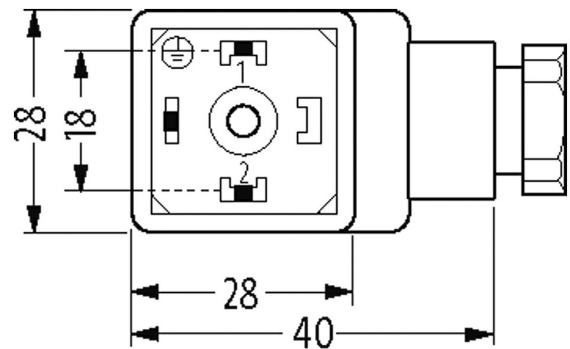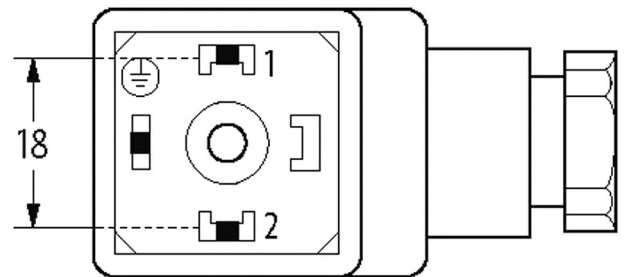

Height: 31,7 mm

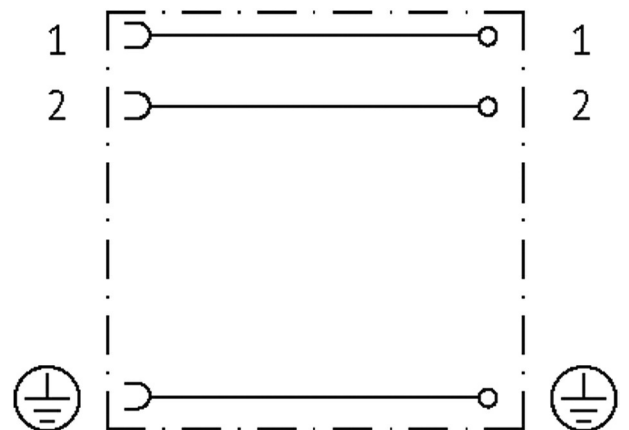

Product may differ from Image

**Approvals**

EAC

**Form**

Form 29245

**General data**

Temperature range -40...+90 °C

Material (gasket) NBR

Mounting method inserted, tightened

Housing PA6 GF30: black

Printing None

**Technical Data**

Operating voltage max. 250 V AC/DC

Operating current per contact max. 10 A

Configuration 2 contacts + PE

Connection cross section 0.5...1.5 mm<sup>2</sup>

Sealing range (cable Ø) 6...8 mm

Locking of ports M3 (recommended torque 0.4 Nm)

Compression gland M16×1.5 mm

Tightening torque (clamp screw) 0.2 ±0.1 Nm

Tightening torque (cable compression gland) 1.8 ±0.2 Nm

Contact figure Cable outlet can be turned in 90° steps

Protection IP65 inserted and tightened (EN 60529)

**Commercial data**

country of origin HU

customs tariff number 85366990

EAN 4048879187527

eClass 27279221

Packaging unit 1