

## **SVS ECO VALVE PLUG FORM A 18MM 250V**

3+PE field-wireable M20x1,5

Form A (18 mm) for pressure switch

250 V AC/DC

without components

metric



field-wireable

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

### [Link to Product](#)

**Illustration**

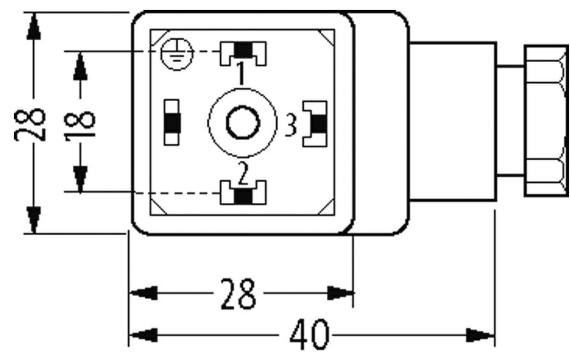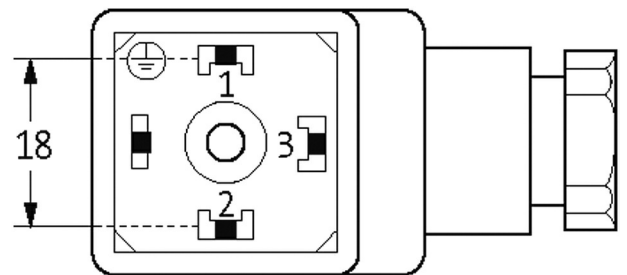

Height: 31.7 mm

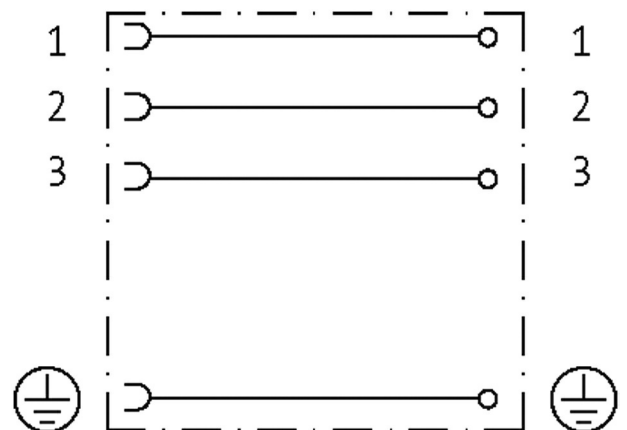

Product may differ from Image

Form	
Form	29415
General data	
Temperature range	-40...+90 °C
Material (gasket)	NBR
Mounting method	inserted, tightened
Housing	PA6 GF30: black
Printing	None
Technical Data	
Operating voltage	max. 250 V AC/DC
Operating current	max. 10 A
Configuration	3 + PE
Connection cross section	0.5...1.5 mm <sup>2</sup>
Sealing range (cable Ø)	8...10 mm
Locking of ports	M3 (recommended torque 0.4 Nm)
Compression gland	M20×1.5 mm
Tightening torque (clamp screw)	0.2 ±0.1 Nm
Tightening torque (cable compression gland)	1.8 ±0.2 Nm
Contact figure	Cable outlet can be turned in 90° steps
Protection	IP65 inserted and tightened (EN 60529)
Commercial data	
country of origin	HU
customs tariff number	85366990
EAN	4048879294485
eClass	27279221
Packaging unit	1