

## SVS VALVE PLUG FORM A 18MM FIELD-WIREABLE

0...230V PG9

Form A (18 mm) for pressure switch

0...230 V AC/DC

without components



PG9

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

### [Link to Product](#)

Illustration

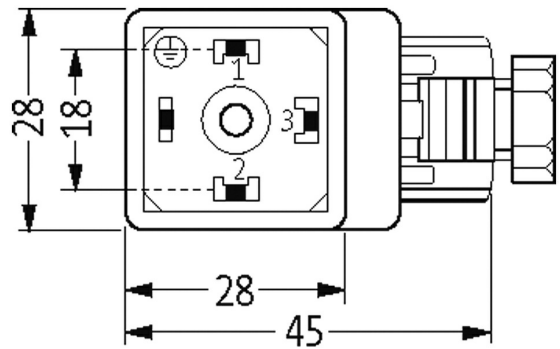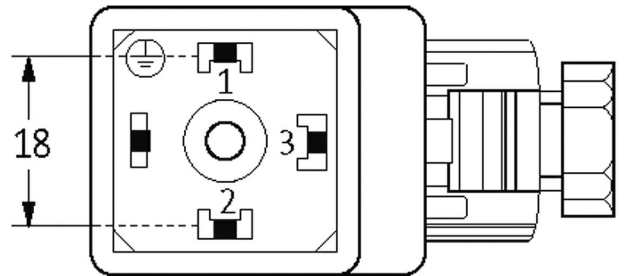

Height: 41 mm

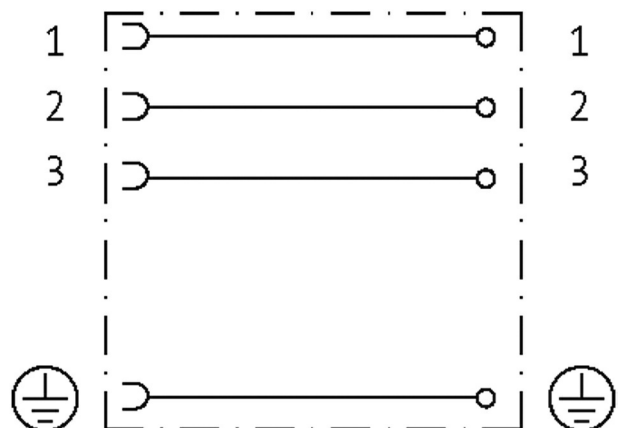

Product may differ from Image

**Form**

Form	29421
------	-------

**General data**

Temperature range	-20...+60 °C
-------------------	--------------

**Technical Data**

Operating voltage	max. 230 V AC/DC
-------------------	------------------

Operating current per contact	max. 10 A
-------------------------------	-----------

Configuration	3 contacts + PE
---------------	-----------------

Locking of ports	M3 (recommended torque 0.4 Nm)
------------------	--------------------------------

Protection	IP65 inserted and tightened (EN 60529)
------------	--

**Commercial data**

country of origin	CZ
-------------------	----

customs tariff number	85366990
-----------------------	----------

EAN	4048879187428
-----	---------------

eClass	27279221
--------	----------

Packaging unit	1
----------------	---