

## SVS VALVE PLUG FORM B 10 MM FIELD-WIREABLE

24V LED+Z-Diode M16x1.5

Form B (10 mm)

24 V AC  $\pm 20\%$  / DC  $\pm 25\%$

LED and Z-diode



metric

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

### [Link to Product](#)

Illustration

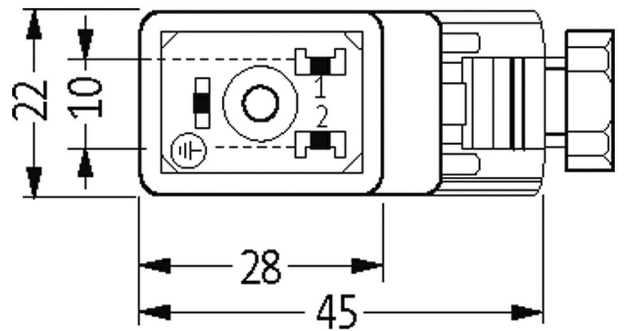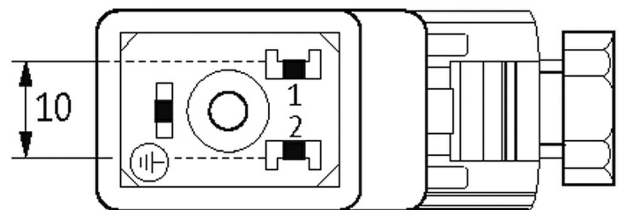

Height: 41 mm

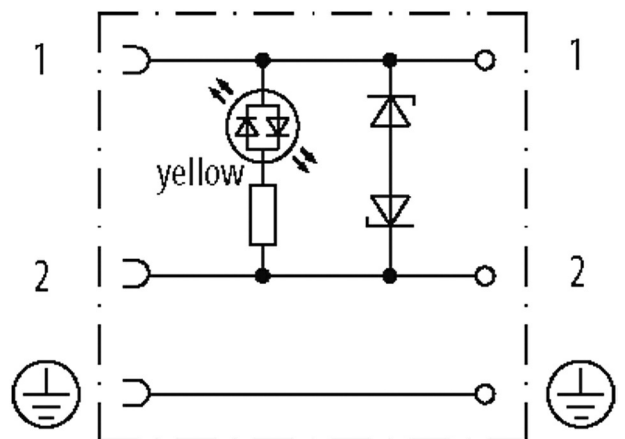

Product may differ from Image

**Form**

Form 29561

**General data**

Temperature range -20...+60 °C

**Technical Data**Operating voltage 24 V AC  $\pm 20\%$  / DC  $\pm 25\%$ 

Operating current per contact max. 4 A

Configuration 2 contacts + PE

Locking of ports M3 (recommended torque 0.4 Nm)

Protection IP65 inserted and tightened (EN 60529)

**Commercial data**

country of origin CZ

customs tariff number 85366990

EAN 4048879187350

eClass 27279221

Packaging unit 1