

SVS VALVE PLUG FORM B 10 MM FIELD-WIREABLE

230V LED+VDR M16x1.5



Form B (10 mm)
230 V AC/DC $\pm 10\%$
LED and VDR
metric

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

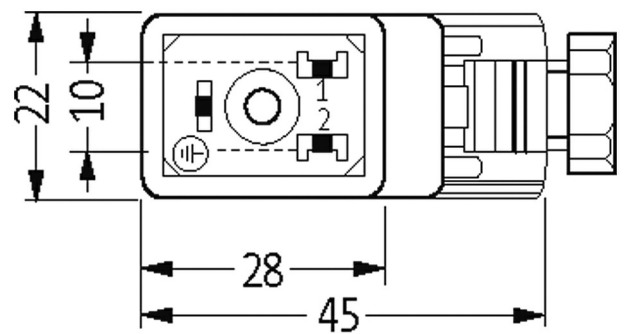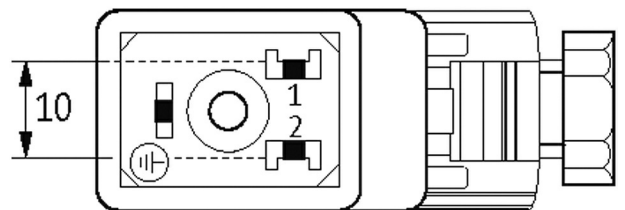

Height: 41 mm

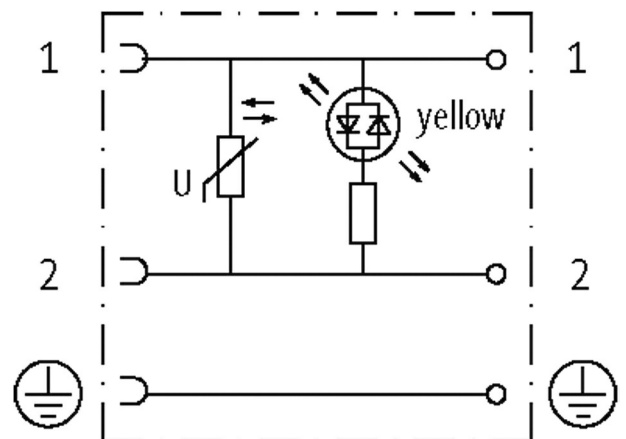

Product may differ from Image

Form

Form 29681

General data

Temperature range -20...+60 °C

Technical Data

Operating voltage 230 V AC/DC ±10%

LED display (yellow)

Current consumption approx. 12 mA

Switch off peak max. 450 V

Switch off delay time max. 15 ms

max. power (W) max. 100 W (VA)

Compression gland M16×1.5 mm

Sealing range (cable Ø) 5...10 mm

Plug color Black housing, transparent flip top

Protection IP65 inserted and tightened (EN 60529), with gland

Locking of ports M3 (recommended torque 0.4 Nm)

Connection cross section 1.5 mm² (with ferrule end)

Operating current per contact max. 1 A

Commercial data

country of origin CZ

customs tariff number 85366990

EAN 4048879187275

eClass 27279221

Packaging unit 1