

SVS ECO VALVE PLUG FORM B 10 MM 230V

2+PE field-wireable M16x1.5



Form B (10 mm)
250 V AC/DC
without components
metric
field-wireable

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

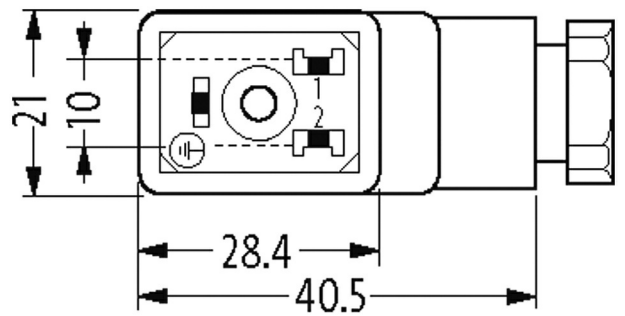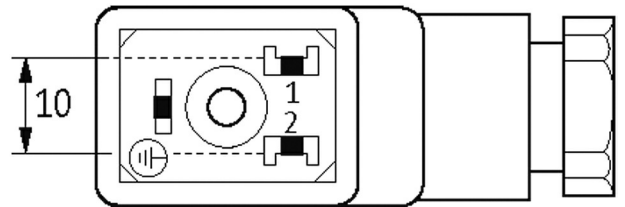

Height: 31.7 mm

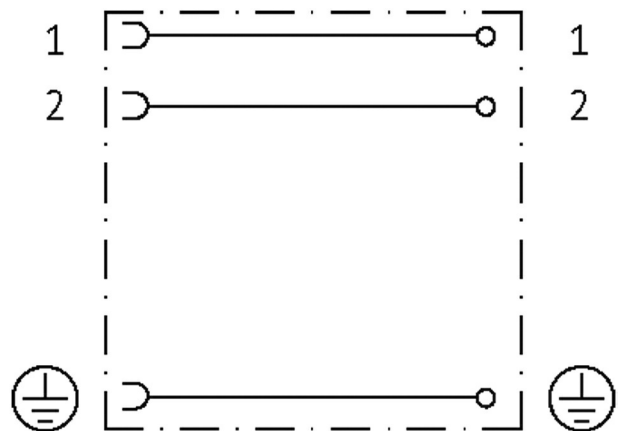

Product may differ from Image

Approvals

EAC

Form

Form 29765

General data

Temperature range -40...+90 °C

Material (gasket) NBR

Mounting method inserted, tightened

Housing PA6 GF30: black

Printing None

Technical Data

Operating voltage max. 250 V AC/DC

Operating current per contact max. 10 A

Configuration 2 contacts + PE

Connection cross section 0.5...1.5 mm²

Sealing range (cable Ø) 6...8 mm

Locking of ports M3 (recommended torque 0.4 Nm)

Compression gland M16×1.5 mm

Tightening torque (clamp screw) 0.2 ±0.1 Nm

Tightening torque (cable compression gland) 1.8 ±0.2 Nm

Contact figure Cable outlet can be turned in 180° steps

Protection IP65 inserted and tightened (EN 60529)

Commercial data

country of origin HU

customs tariff number 85366990

EAN 4048879187213

eClass 27279221

Packaging unit 1