

SVS VALVE PLUG FORM BI 11MM FIELD-WIREABLE

24V LED+Z-Diode M16x1.5

Form BI (11 mm)

24 V AC $\pm 20\%$ / DC $\pm 25\%$

LED and Z-diode



metric

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

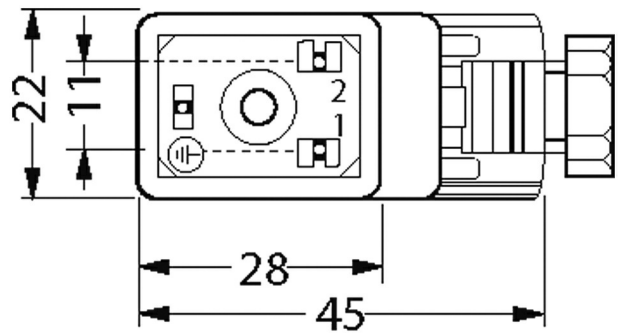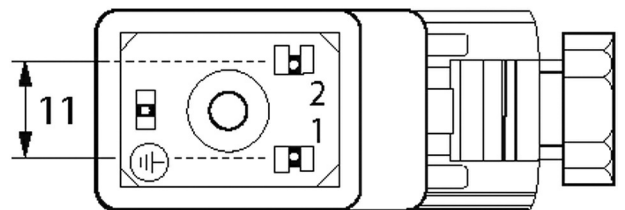

Height: 41 mm

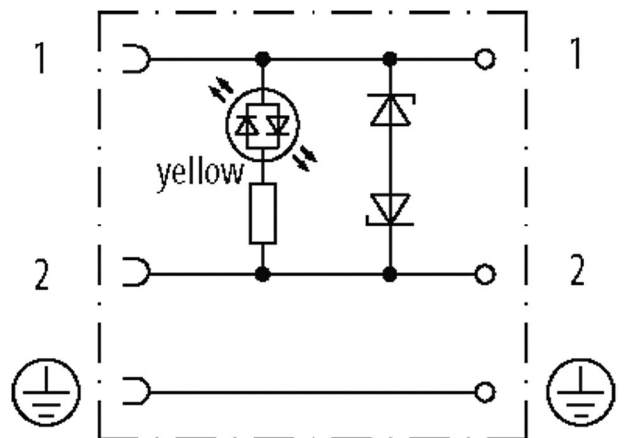

Product may differ from Image

Form

Form 29801

General data

Temperature range -20...+60 °C

Technical DataOperating voltage 24 V AC $\pm 20\%$ / DC $\pm 25\%$

Operating current per contact max. 4 A

Configuration 2 contacts + PE

Locking of ports M3 (recommended torque 0.4 Nm)

Protection IP65 inserted and tightened (EN 60529)

Commercial data

country of origin CZ

customs tariff number 85366990

EAN 4048879187190

eClass 27279221

Packaging unit 1