

SVS VALVE PLUG FORM BI 11MM FIELD-WIREABLE

24V LED+RC M16x1.5



Form BI (11 mm)
max. 24 V AC/DC
LED and RC
metric

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

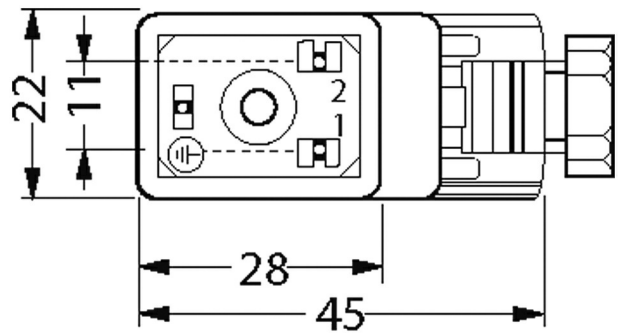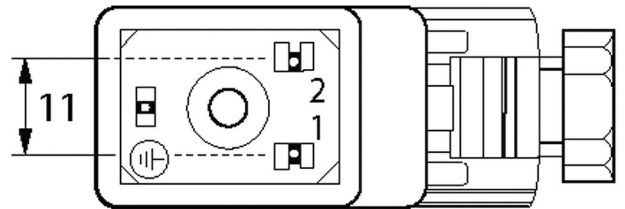

Height: 41 mm

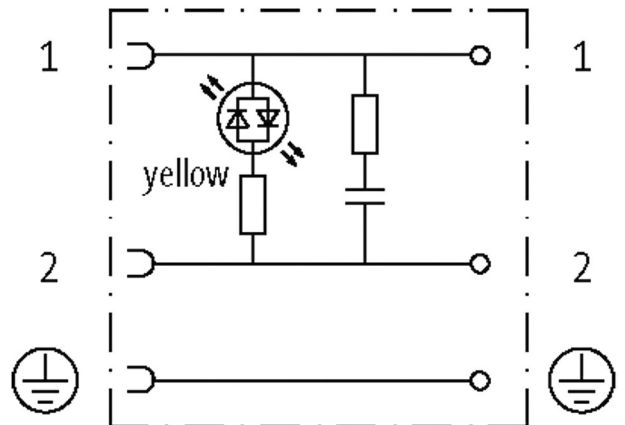

Product may differ from Image